


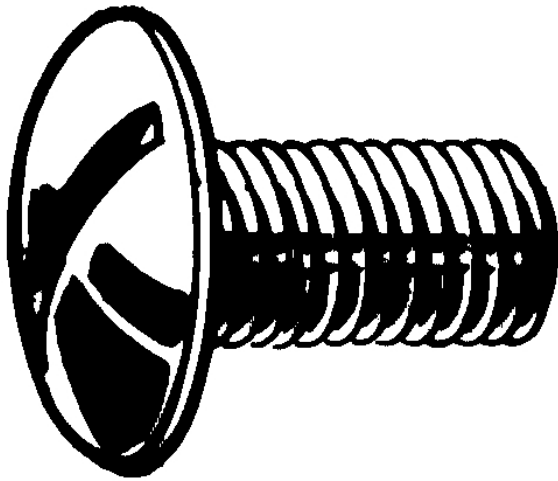

Slotted mushroom head screw NF ≈E25-129 Stainless steel A2 M6X10

Article number	51215.060.010
Brand	-
UBB	950353684067
UNSPSC	31161504
EAN	8715492275820
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M6
Length	10 mm
Driving features	Slotted
Head shape	Button head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

NF	≈E25-129
----	----------

Technical Specification

d-D	M6
Thread length (min.)	38
dk (max.)	15
Full thread if L ≤	60
k (max.)	3.3
L (mm)	10
n	1.9
P	1
t (min.)	1.5

Technical Drawing

