


Strukturbausatz, CE EN 15048 Stahl Elektrolytisch verzinkt 8.8/8 M12X70

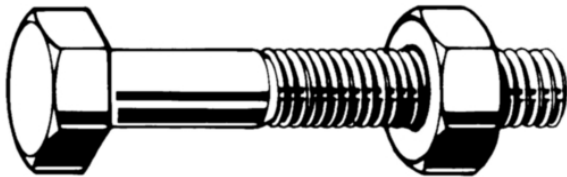

Artikelnummer	01222.120.070
Marke	-
UBB	500574451869
UNSPSC	31161620
EAN	8715494305822
PKG. von 50	Nur komplette Verpackung

Technische Parameter

Durchmesser (d-D)	M12
Länge (L) (mm)	70
Klasse	8.8/8
Material	Stahl
Oberfläche	Elektrolytisch verzinkt
Kopfform	Sechskantkopf
Antriebsart	Außensechskant
Gewinderichtung	Rechts
Gewinde	Metrisches Gewinde
Schlüsselweite	18

Standards

ISO	4014/4032
EN	15048

Info

Full boxes only. European constructions must comply with the Construction Products Regulation (CPR) in order to ensure the safety of persons and objects. Generally, construction products according to harmonized European standards (hEN standards) should be used for this purpose. Bolting

assemblies for non-preloaded structural bolting according to EN 15048-1 are compliant with the CPR. The manufacturer of the assemblies is CE certified for their production. Bolts and nuts are packaged together in single sealed boxes. A Declaration of Performance (DoP) is available.

Technische Spezifikation

b (min.): 125mm $L \leq 200\text{mm}$	36
b (min.): $L > 200\text{mm}$	49
b (min.): $L \leq 125\text{mm}$	30
k	7.5
m (max.)	10.8
P	1.75
s	18

Technische Zeichnung

