


Strukturbausatz, CE EN 15048 Stahl Elektrolytisch verzinkt 8.8/8 M20X70

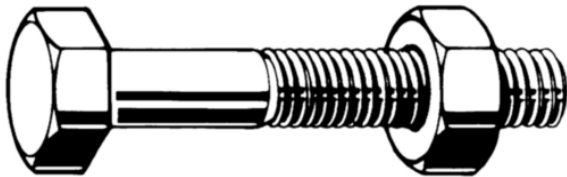

Artikelnummer	01222.200.070
Marke	-
UBB	500574453840
UNSPSC	31161620
EAN	8715494306027
PKG. von 25	Nur komplette Verpackung

Technische Parameter

Durchmesser (d-D)	M20
Länge (L) (mm)	70
Klasse	8.8/8
Material	Stahl
Oberfläche	Elektrolytisch verzinkt
Kopfform	Sechskantkopf
Antriebsart	Außensechskant
Gewinderichtung	Rechts
Gewinde	Metrisches Gewinde

Standards

EN	15048
ISO	4014/4032

Info

Full boxes only. European constructions must comply with the Construction Products Regulation (CPR) in order to ensure the safety of persons and objects. Generally, construction products according to harmonized European standards (hEN standards) should be used for this purpose. Bolting assemblies for non-

FABORY

preloaded structural
bolting according
to EN 15048-1
are compliant with
the CPR. The
manufacturer of
the assemblies
is CE certified for
their production.
Bolts and nuts are
packaged together in
single sealed boxes.
A Declaration of
Performance (DoP)
is available.

Technische Spezifikation

b (min.): 125mm $L \leq 200\text{mm}$	52
b (min.): $L > 200\text{mm}$	65
b (min.): $L \leq 125\text{mm}$	46
k	12.5
m (max.)	18
P	2.50
s	30

Technische Zeichnung

