


Strukturbausatz, CE EN 15048 Stahl Elektrolytisch verzinkt 8.8/8 M24X130

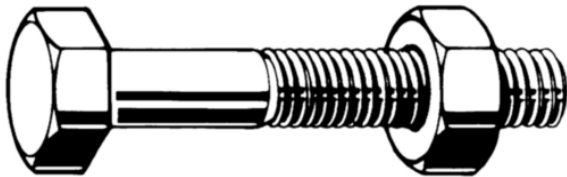

Artikelnummer	01222.240.130
Marke	-
UBB	500574455332
UNSPSC	31161620
EAN	8715494311144
PKG. von 10	Nur komplette Verpackung

Technische Parameter

Durchmesser (d-D)	M24
Länge (L) (mm)	130
Klasse	8.8/8
Material	Stahl
Oberfläche	Elektrolytisch verzinkt
Kopfform	Sechskantkopf
Antriebsart	Außensechskant
Gewinderichtung	Rechts
Gewinde	Metrisches Gewinde

Info

Full boxes only. European constructions must comply with the Construction Products Regulation (CPR) in order to ensure the safety of persons and objects. Generally, construction products according to harmonized European standards (hEN standards) should be used for this purpose. Bolting assemblies for non-

Standards

ISO	4014/4032
EN	15048

FABORY

preloaded structural bolting according to EN 15048-1 are compliant with the CPR. The manufacturer of the assemblies is CE certified for their production. Bolts and nuts are packaged together in single sealed boxes. A Declaration of Performance (DoP) is available.

Technische Spezifikation

b (min.): 125mm $L \leq 200\text{mm}$	60
b (min.): $L > 200\text{mm}$	73
b (min.): $L \leq 125\text{mm}$	54
k	15
m (max.)	21.5
P	3
s	36

Technische Zeichnung

