

Kerbstifte in voller Länge schräg gerillt DIN 1471 DIN 1471 Automatenstahl 2X5MM



Artikelnummer	39710.020.005
Marke	-
UBB	950359125263
UNSPSC	31163215
EAN	8715492823953
PKG. von 200	Nur komplette Verpackung

Technische Parameter

Durchmesser	2 mm
Länge	5 mm
Material	Automatenstahl

Info V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1471
NEN	≈2602
ISO	≈8744

Technische Spezifikation

c ≈	0.25
d1	2
d2 ≈	2.15
D (mm)	2
L (mm)	5

Technische Zeichnung

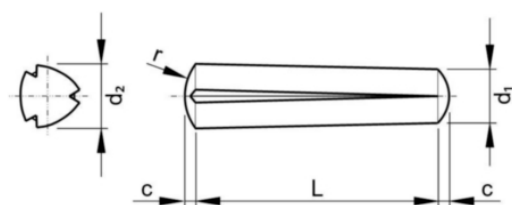

$r \approx 2$

Tolerance h9

V 2.85