

Zylinderkerbstifte mit Fase [*] DIN 1473 Automatenstahl 1,5X8MM



Artikelnummer	39730.015.008
Marke	-
UBB	950359657224
UNSPSC	31163215
EAN	8715492825728
PKG. von 200	Nur komplette Verpackung

Technische Parameter

Durchmesser	1.5 mm
Länge	8 mm
Material	Automatenstahl
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1473
ISO	≈8740
NEN	≈2604

Technische Spezifikation

c ≈	0.2
d1	1.5
d2 ≈	1.6
D (mm)	1.5
f ≈	0.8

Technische Zeichnung

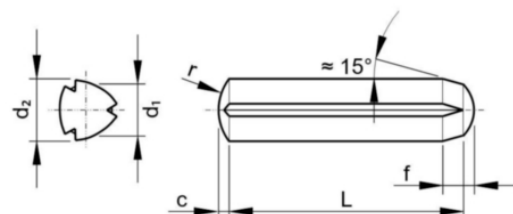

L (mm)	8
$r \approx$	1.5
Tolerance	h9
V	1.6