

Zylinderkerbstifte mit Fase [*] DIN 1473 Automatenstahl 3X6MM



Artikelnummer	39730.030.006
Marke	-
UBB	950359659204
UNSPSC	31163215
EAN	8715492825957
PKG. von 200	Nur komplette Verpackung

Technische Parameter

Durchmesser	3 mm
Länge	6 mm
Material	Automatenstahl

Info

V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

ISO	≈8740
DIN	1473
NEN	≈2604

Technische Spezifikation

c ≈	0.4
d1	3
d2 ≈	3.2
D (mm)	3
f ≈	1.3

Technische Zeichnung

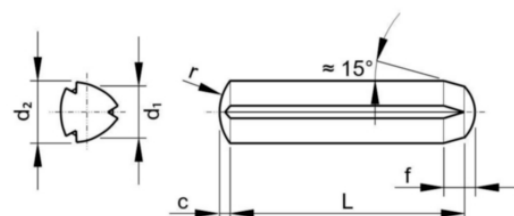

L (mm)	6
$r \approx$	3
Tolerance	h9
V	6.15