

Zylinderkerbstifte mit Fase [*] DIN 1473 Automatenstahl 3X30MM



Artikelnummer	39730.030.030
Marke	-
UBB	950359659873
UNSPSC	31163215
EAN	8715492826022
PKG. von 200	Nur komplette Verpackung

Technische Parameter

Durchmesser	3 mm
Länge	30 mm
Material	Automatenstahl

Info V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

NEN	≈2604
DIN	1473
ISO	≈8740

Technische Spezifikation

c ≈	0.4
d1	3
d2 ≈	3.2
D (mm)	3
f ≈	1.3

Technische Zeichnung

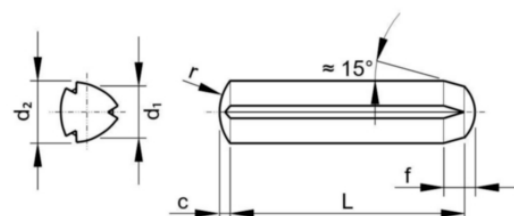

L (mm)	30
$r \approx$	3
Tolerance	h9
V	6.15