

Zylinderkerbstifte mit Fase [*] DIN 1473 Automatenstahl 4X36MM



Artikelnummer	39730.040.036
Marke	-
UBB	950359660681
UNSPSC	31163215
EAN	8715492826121
PKG. von 100	Nur komplette Verpackung

Technische Parameter

Durchmesser	4 mm
Länge	36 mm
Material	Automatenstahl
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1473
NEN	≈2604
ISO	≈8740

Technische Spezifikation

c ≈	0.4
d1	4
d2 ≈	4.25
D (mm)	4
f ≈	1.8

Technische Zeichnung

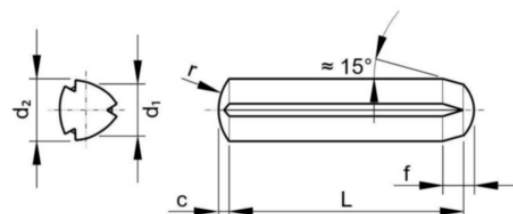

L (mm)	36
$r \approx$	4
Tolerance	h11
V	10.6