

Fischer Wanddübel universell Kunststoff Nylon (polyamid) FU 8X50



Artikelnummer	63270.080.050
Marke	-
UBB	950372028684
UNSPSC	31162103
EAN	4006209532645
PKG. von 50	Nur komplette Verpackung

Technische Parameter


Durchmesser	8 mm
Länge	50 mm
Farbe	Grau
Material	Plastic
Typ Nr.	FU
Info	Allowable load in kN at the largest possible screw diameter, (values in bold print), and a correct mounting of the wall plug in a supporting surface. Allowable load includes the safety factor 7.

Standards

Technische Spezifikation

Brick Mz12	0.5
Cellular concrete PB2, PP2 (G2)	0.09
Cellular concrete PB4, PP4 (G4)	0.22
Concrete C20/25	0.57
D (mm)	8
Drill depth (min.)	60

Technische Zeichnung

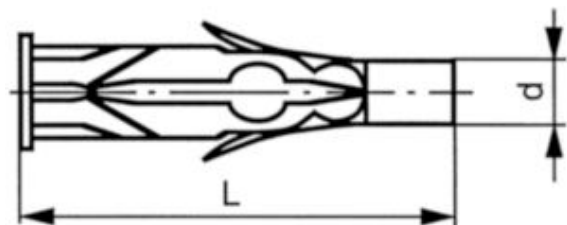

Drill ø	8
L (mm)	50
Material thickness (min.)	6
Pumice grit V2	0.21
Sandlime brick KS12	0.5
Type	FU 8X50
Holz- und Spanplattenschrauber	4.5