


Hexagon head bolt DIN 931 Steel Plain 8.8 M10X35

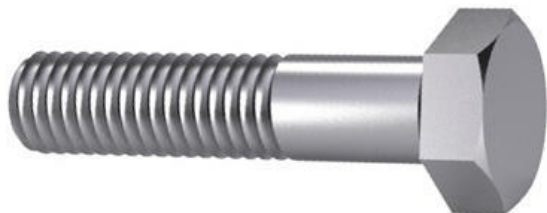

Article number	01000.100.035
Brand	-
UBB	500621727345
UNSPSC	31161620
EAN	8715494501668
PKG. of 100	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width (s) (mm)	17
Diameter (d-D)	M10
Length (L) (mm)	35

Standards

ASME	B18.2.3.1M
ISO	4014
NF	E25-112
DIN	931

Technical Specification

b (min.): 125mm<L≤200mm	32
b (min.): L>200mm	45
b (min.): L≤125mm	26
k	6.4
P	1.50
s	17

Technical Drawing

