


## Hexagon head bolt DIN 931 Steel Right Plain 8.8 M10X45/ S=17

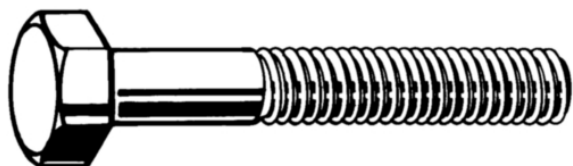

Article No.	01000.100.045
Brand	-
UBB	950351005448
UNSPSC	31161620
EAN	8715492007629
PKG. of 100	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	17
Diameter (d-D)	M10
Length (L) (mm)	45

### Standards

ASME	B18.2.3.1M
ISO	4014
NEN	1555
DIN	931
NF	E25-112

### Technical Specification

s	17
k	6.4
P	1.50
b (min.): L≤125mm	26
b (min.): L>200mm	45
b (min.): 125mm<L≤200mm	32

### Technical Drawing

