


Hexagon head bolt DIN 931 Steel Right Plain 8.8 M12X50/ S=19

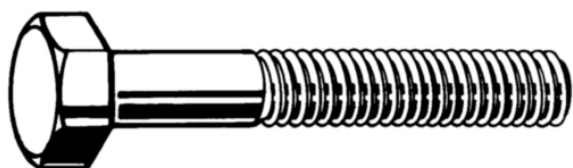

Article No.	01000.120.050
Brand	-
UBB	950351007428
UNSPSC	31161620
EAN	8715492007940
PKG. of 100	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	19
Diameter (d-D)	M12
Length (L) (mm)	50

Standards

NF	E25-112
ASME	B18.2.3.1M
NEN	1555
DIN	931
ISO	4014

Technical Specification

k	7.5
b (min.): 125mm<L≤200mm	36
b (min.): L≤125mm	30
P	1.75
b (min.): L>200mm	49
s	19

Technical Drawing

