


Hexagon head bolt DIN 931 Steel Right Plain 8.8 M12X100/S=19

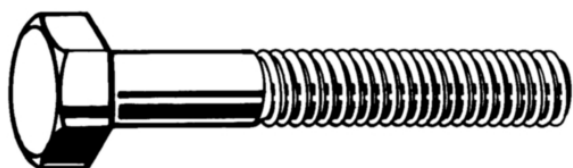

Article No.	01000.120.100
Brand	-
UBB	950351008251
UNSPSC	31161620
EAN	8715492008053
PKG. of 50	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	19
Diameter (d-D)	M12
Length (L) (mm)	100

Standards

NEN	1555
ISO	4014
ASME	B18.2.3.1M
DIN	931
NF	E25-112

Technical Specification

b (min.): 125mm<L≤200mm	36
s	19
b (min.): L≤125mm	30
P	1.75
k	7.5
b (min.): L>200mm	49

Technical Drawing

