


Hexagon head bolt DIN 931 Steel Right Plain 8.8 M12X110/S=19

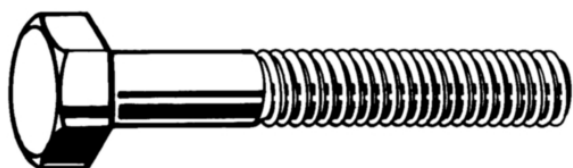

Article No.	01000.120.110
Brand	-
UBB	950351008335
UNSPSC	31161620
EAN	8715492008060
PKG. of 50	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	19
Diameter (d-D)	M12
Length (L) (mm)	110

Standards

NF	E25-112
ASME	B18.2.3.1M
ISO	4014
DIN	931
NEN	1555

Technical Specification

s	19
b (min.): $L \leq 125\text{mm}$	30
b (min.): $L > 200\text{mm}$	49
b (min.): $125\text{mm} < L \leq 200\text{mm}$	36
P	1.75
k	7.5

Technical Drawing

