


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M12X170

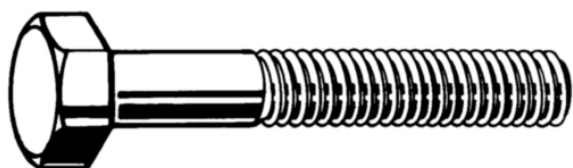

Article No. 01000.120.170

Brand -

UBB 950351903394

UNSPSC 31161620

EAN 8715492008121

PKG. of 25 Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	19
Diameter (d-D)	M12
Length (L) (mm)	170

Standards

ASME	B18.2.3.1M
NF	E25-112
NEN	1555
ISO	4014
DIN	931

Technical Specification

b (min.): $L \leq 125\text{mm}$	30
b (min.): $L > 200\text{mm}$	49
b (min.): $125\text{mm} < L \leq 200\text{mm}$	36
k	7.5
s	19
P	1.75

Technical Drawing

