


Hexagon head bolt DIN 931 Steel Right Plain 8.8 M14X75/ S=22

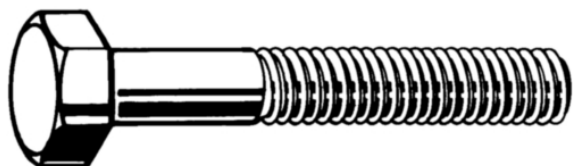

Article No.	01000.140.075
Brand	-
UBB	950351010133
UNSPSC	31161620
EAN	8715492008299
PKG. of 50	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	22
Diameter (d-D)	M14
Length (L) (mm)	75

Standards

DIN	931
ASME	B18.2.3.1M
NEN	1555
NF	E25-112
ISO	4014

Technical Specification

b (min.): 125mm<L≤200mm	40
b (min.): L≤125mm	34
k	8.8
P	2
s	22
b (min.): L>200mm	53

Technical Drawing

