


Hexagon head bolt DIN 931 Steel Right Plain 8.8 M14X200/S=22

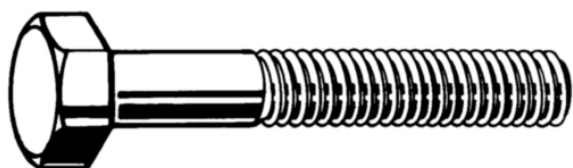

Article No.	01000.140.200
Brand	-
UBB	950351011206
UNSPSC	31161620
EAN	8715492008435
PKG. of 25	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	22
Diameter (d-D)	M14
Length (L) (mm)	200

Standards

NF	E25-112
NEN	1555
DIN	931
ISO	4014
ASME	B18.2.3.1M

Technical Specification

b (min.): $L \leq 125\text{mm}$	34
P	2
b (min.): $125\text{mm} < L \leq 200\text{mm}$	40
s	22
b (min.): $L > 200\text{mm}$	53
k	8.8

Technical Drawing

