


Hexagon head bolt ISO 4014 Steel Right Plain 8.8 M16X130

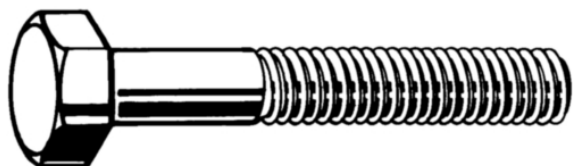

Article No.	01000.160.130
Brand	-
UBB	950351012378
UNSPSC	31161620
EAN	8715492008619
PKG. of 25	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M16
Length (L) (mm)	130

Standards

ISO	4014
NF	E25-112
DIN	931
ASME	B18.2.3.1M
NEN	1555

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	44
s	24
b (min.): $L > 200\text{mm}$	57
k	10
b (min.): $L \leq 125\text{mm}$	38
P	2

Technical Drawing

