


## Hexagon head bolt ISO 4014 Steel Right Plain 8.8 M16X340

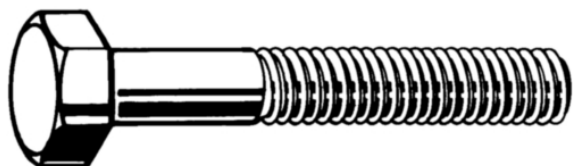

Article No.	01000.160.340
Brand	-
UBB	952351314069
UNSPSC	31161620
EAN	8715492008794
PKG. of 10	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M16
Length (L) (mm)	340

### Standards

NEN	1555
NF	E25-112
ISO	4014
ASME	B18.2.3.1M
DIN	931

### Technical Specification

k	10
P	2
b (min.): L≤125mm	38
b (min.): L>200mm	57
b (min.): 125mm<L≤200mm	44
s	24

### Technical Drawing

