


## Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M22X80

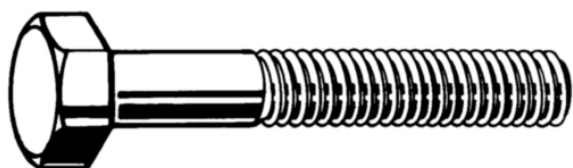

Article No.	01000.220.080
Brand	-
UBB	950351018078
UNSPSC	31161620
EAN	8715492009524
PKG. of 25	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	32
Diameter (d-D)	M22
Length (L) (mm)	80

### Standards

ISO	4014
NF	E25-112
NEN	1555
DIN	931
ASME	B18.2.3.1M

### Technical Specification

s	32
k	14
b (min.): 125mm<L≤200mm	56
b (min.): L≤125mm	50
P	2.50
b (min.): L>200mm	69

### Technical Drawing

