


Hexagon head bolt DIN 931 Steel Plain 8.8 M22X100

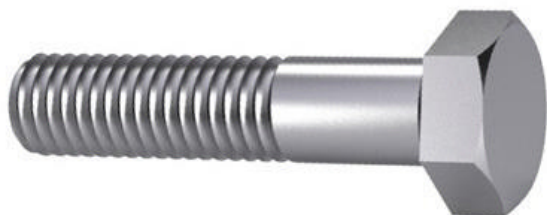

Article number	01000.220.100
Brand	-
UBB	950351018235
UNSPSC	31161620
EAN	8715492009555
PKG. of 10	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width (s) (mm)	32
Diameter (d-D)	M22
Length (L) (mm)	100

Standards

ASME	B18.2.3.1M
NF	E25-112
DIN	931
ISO	4014

Technical Specification

b (min.): 125mm<L≤200mm	56
b (min.): L>200mm	69
b (min.): L≤125mm	50
k	14
P	2.50
s	32

Technical Drawing

