


## Hexagon head bolt DIN 931 Steel Right Plain 8.8 M22X100/S=32

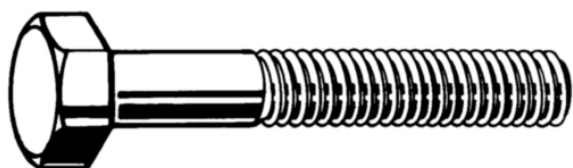

|             |               |
|-------------|---------------|
| Article No. | 01000.220.100 |
| Brand       | -             |
| UBB         | 950351018235  |
| UNSPSC      | 31161620      |
| EAN         | 8715492009555 |
| PKG. of 10  | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Class             | 8.8           |
| Driving features  | Hexagon       |
| Head shape        | Hexagon head  |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Plain         |
| Thread            | Metric thread |
| Wrench width      | 32            |
| Diameter (d-D)    | M22           |
| Length (L) (mm)   | 100           |

### Standards

|      |            |
|------|------------|
| ISO  | 4014       |
| NEN  | 1555       |
| DIN  | 931        |
| ASME | B18.2.3.1M |
| NF   | E25-112    |

### Technical Specification

|                            |      |
|----------------------------|------|
| b (min.):<br>125mm<L≤200mm | 56   |
| b (min.): L≤125mm          | 50   |
| k                          | 14   |
| P                          | 2.50 |
| s                          | 32   |
| b (min.): L>200mm          | 69   |

### Technical Drawing

