


## Hexagon head bolt DIN 931 Steel Right Plain 8.8 M22X110/S=32

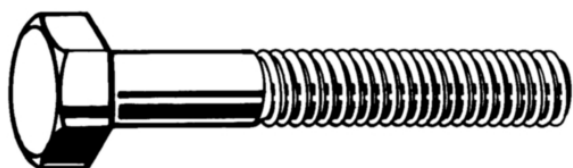

Article No.	01000.220.110
Brand	-
UBB	950351018318
UNSPSC	31161620
EAN	8715492009562
PKG. of 10	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	32
Diameter (d-D)	M22
Length (L) (mm)	110

### Standards

ISO	4014
NEN	1555
NF	E25-112
DIN	931
ASME	B18.2.3.1M

### Technical Specification

k	14
b (min.): 125mm<L≤200mm	56
s	32
P	2.50
b (min.): L>200mm	69
b (min.): L≤125mm	50

### Technical Drawing

