


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M27X140

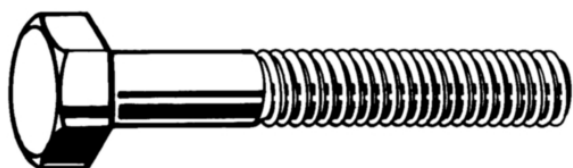

Article No.	01000.270.140
Brand	-
UBB	950351022682
UNSPSC	31161620
EAN	8715492010223
PKG. of 10	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M27
Length (L) (mm)	140

Standards

ASME	B18.2.3.1M
NF	E25-112
ISO	4014
DIN	931
NEN	1555

Technical Specification

k	17
b (min.): $L > 200\text{mm}$	79
b (min.): $125\text{mm} < L \leq 200\text{mm}$	66
b (min.): $L \leq 125\text{mm}$	60
s	41
P	3

Technical Drawing

