


## Hexagon head bolt ISO 4014 Steel Right Plain 8.8 M30X130

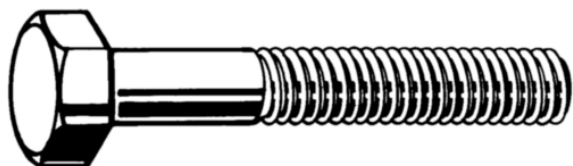

Article No.	01000.300.130
Brand	-
UBB	950351024746
UNSPSC	31161620
EAN	8715492010490
PKG. of 10	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M30
Length (L) (mm)	130

### Standards

DIN	931
ISO	4014
NEN	1555
NF	E25-112
ASME	B18.2.3.1M

### Technical Specification

b (min.): $L \leq 125\text{mm}$	66
s	46
k	18.7
P	3.50
b (min.): $L > 200\text{mm}$	85
b (min.): $125\text{mm} < L \leq 200\text{mm}$	72

### Technical Drawing

