


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M30X140

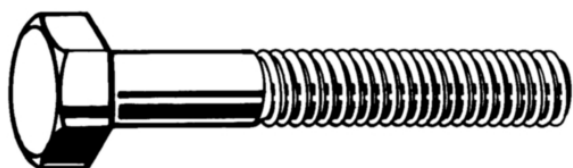

Article No.	01000.300.140
Brand	-
UBB	950351024829
UNSPSC	31161620
EAN	8715492010506
PKG. of 10	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M30
Length (L) (mm)	140

Standards

NF	E25-112
ISO	4014
NEN	1555
ASME	B18.2.3.1M
DIN	931

Technical Specification

P	3.50
b (min.): L>200mm	85
k	18.7
b (min.): 125mm<L≤200mm	72
s	46
b (min.): L≤125mm	66

Technical Drawing

