


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M36X270

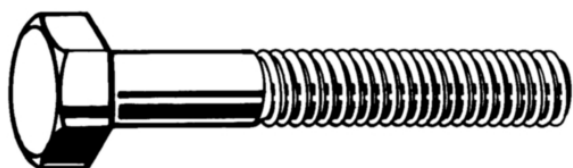

Article No.	01000.360.270
Brand	-
UBB	952351966496
UNSPSC	31161620
EAN	8715492011213
PKG. of 2	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M36
Length (L) (mm)	270

Standards

NF	E25-112
NEN	1555
ASME	B18.2.3.1M
ISO	4014
DIN	931

Technical Specification

b (min.): $L \leq 125\text{mm}$	78
P	4
b (min.): $L > 200\text{mm}$	97
b (min.): $125\text{mm} < L \leq 200\text{mm}$	84
s	55
k	22.5

Technical Drawing

