


## Hexagon head bolt ISO 4014 Steel Right Plain 8.8 M39X160

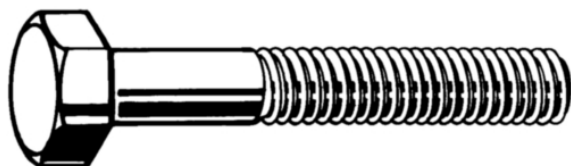

Article No.	01000.390.160
Brand	-
UBB	950351031188
UNSPSC	31161620
EAN	8715492011435
PKG. of 1	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M39
Length (L) (mm)	160

### Standards

ASME	B18.2.3.1M
NEN	1555
NF	E25-112
DIN	931
ISO	4014

### Technical Specification

b (min.): $L \leq 125\text{mm}$	84
b (min.): $125\text{mm} < L \leq 200\text{mm}$	90
k	25
P	4
b (min.): $L > 200\text{mm}$	103
s	60

### Technical Drawing

