


## Hexagon head bolt ISO 4014 Steel Right Plain 8.8 M52X320

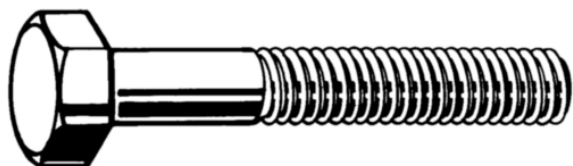

Article No.	01000.520.320
Brand	-
UBB	950351036476
UNSPSC	31161620
EAN	8715492012395
PKG. of 1	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M52
Length (L) (mm)	320

### Standards

NF	E25-112
ASME	B18.2.3.1M
NEN	1555
ISO	4014
DIN	931

### Technical Specification

s	80
b (min.): L>200mm	119
k	33
b (min.): 125mm<L≤200mm	116
P	5

### Technical Drawing

