


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M56X240

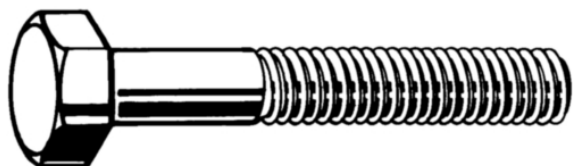

Article No.	01000.560.240
Brand	-
UBB	950351037045
UNSPSC	31161620
EAN	8715492012487
PKG. of 1	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M56
Length (L) (mm)	240

Standards

ASME	B18.2.3.1M
NEN	1555
ISO	4014
NF	E25-112
DIN	931

Technical Specification

b (min.): L>200mm	137
P	5.50
b (min.): 125mm<L≤200mm	124
k	35
s	85

Technical Drawing

