


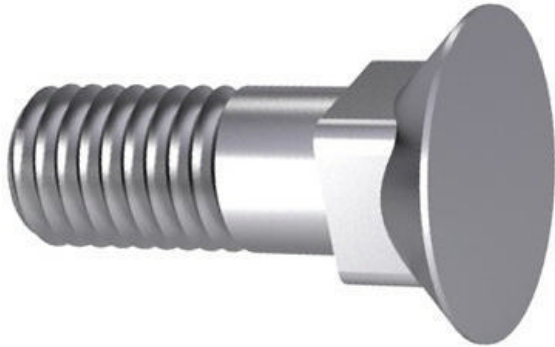

Flat countersunk square neck bolt with short square DIN ≈608 Steel Plain 8.8 M16X40

Article number	01036.160.040
Brand	-
UBB	500644987801
UNSPSC	31161612
EAN	8717077048430
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M16
Length	40 mm
Class	8.8
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	≈608
-----	------

Technical Specification

b (min.)	38
d-D	M16
dk (max.)	32
L (mm)	40
P	2
fn (max.)	13.5
v (max.)	16.7

Technical Drawing

