


Hexagon fit bolt with long thread DIN 609 Steel Plain 8.8 M8X50X36,6

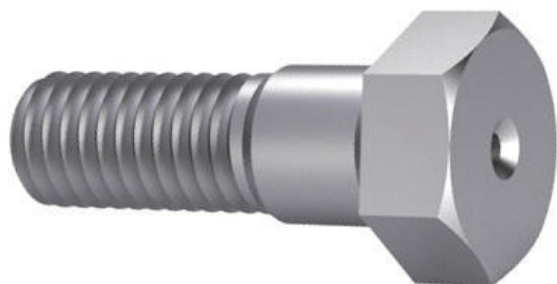

Article number	01040.080.050
Brand	-
UBB	500644607235
UNSPSC	31161620
EAN	8717077009271
PKG. of 25	Full Box Only

Technical Parameters

Diameter (d-D)	M8
Length (L) (mm)	50
Lg (max.)	36.6
Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	609
-----	-----

Technical Specification

b:50mm<L≤150mm	16.5
b (min.): L>150mm	21.5
b:L≤50mm	14.5
d _s (k6)	9 (9,001-9,010)
k	5.3
P	1.25
s	13
Tolerance drill ø	H7

Technical Drawing

