

Hexagon fit bolt with long thread DIN 609 Steel Plain 10.9 M8X25X11,6

Article number	01041.080.025
Brand	-
UBB	500647897908
UNSPSC	31161620
EAN	8717077279889
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M8
Length	25 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.


Standards

DIN	609
-----	-----

Technical Specification

b:50mmL≤150mm	16.5
b (min.): L150mm	21.5
b:L≤50mm	14.5
d-D	M8
ds (k6)	9
k	5.3
L (mm)	25
Lg (max.)	11.6
P	1.25

Technical Drawing

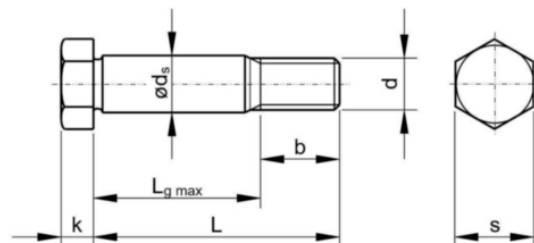

s

13

Tolerance drill $\varnothing$

H7