

Hexagon fit bolt with long thread DIN 609 Steel Plain 10.9 M10X40X23,9

Article number	01041.100.040
Brand	-
UBB	500647898732
UNSPSC	31161620
EAN	8717077279964
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M10
Length	40 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.


Standards

DIN	609
-----	-----

Technical Specification

b:50mmL≤150mm	19.5
b (min.): L150mm	24.5
b:L≤50mm	17.5
d-D	M10
ds (k6)	11
k	6.4
L (mm)	40
Lg (max.)	23.9
P	1.5

Technical Drawing

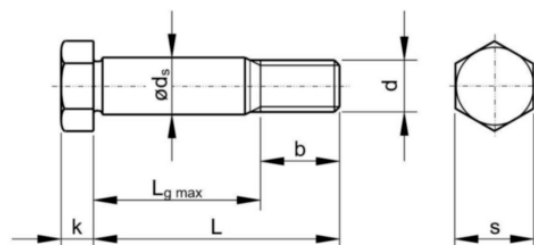

s

16

Tolerance drill $\varnothing$

H7