

## Hexagon fit bolt with long thread DIN 609 Steel Plain 10.9 M10X45X28,9

|                |               |
|----------------|---------------|
| Article number | 01041.100.045 |
| Brand          | -             |
| UBB            | 500647898815  |
| UNSPSC         | 31161620      |
| EAN            | 8717077279971 |
| PKG. of 25     | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M10           |
| Length            | 45 mm         |
| Class             | 10.9          |
| Driving features  | Hexagon       |
| Head shape        | Hexagon head  |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Plain         |
| Thread            | Metric thread |

Info  
Warning:  
electroplating of  
these products may  
cause hydrogen  
embrittlement.


### Standards

|     |     |
|-----|-----|
| DIN | 609 |
|-----|-----|

### Technical Specification

|                  |      |
|------------------|------|
| b:50mmL≤150mm    | 19.5 |
| b (min.): L150mm | 24.5 |
| b:L≤50mm         | 17.5 |
| d-D              | M10  |
| ds (k6)          | 11   |
| k                | 6.4  |
| L (mm)           | 45   |
| Lg (max.)        | 28.9 |
| P                | 1.5  |

### Technical Drawing

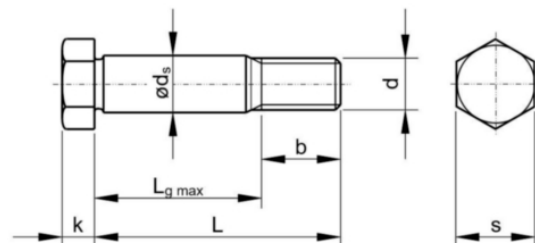

s

16

Tolerance drill  $\varnothing$

H7