


Hexagon flange bolt with toothed flange DIN ≈6921 Steel Plain 100 M16X70

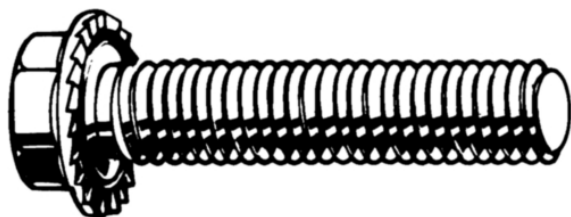

Article number	01050.160.070
Brand	-
UBB	950351126228
UNSPSC	31161620
EAN	8715492019417
PKG. of 25	Full Box Only

Technical Parameters

Diameter (d-D)	M16
Length (L) (mm)	70
Class	100
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	Warning: electroplating of these products may cause hydrogen embrittlement.

Standards

DIN	≈6921
-----	-------

Technical Specification

d_c	31
k	11.2
P	2
s	22

Technical Drawing

