


## Hexagon flange bolt with toothed flange DIN ≈6921 Steel Zinc flake Cr6+free - ISO 10683 fIZnnc 90 M10X30

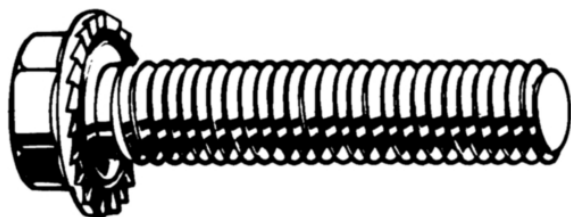

Article number 01055.100.030

Brand -

UBB 500571185932

UNSPSC 31161620

EAN 8715494147422

PKG. of 200 Full Box Only

### Technical Parameters

Diameter (d-D)	M10
Length (L) (mm)	30
Class	90
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc flake Cr(VI) free - fIZn/nc
Thread	Metric thread
Info	A zinc flake coating eliminates the risk of hydrogen embrittlement.

### Standards

DIN ≈6921

### Technical Specification

$d_c$	21
k	7.9
P	1.50
s	15

### Technical Drawing

