


Hexagon head bolt ISO 4014 Steel Zinc plated 8.8 M3X35

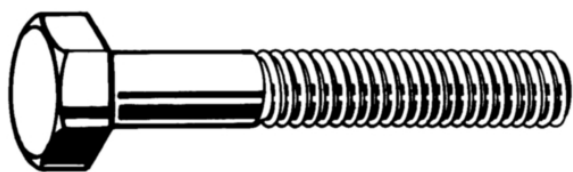

Article No.	01200.030.035
Brand	-
UBB	500644996307
UNSPSC	31161620
EAN	8717077049284
PKG. of 500	Full Box Only

Technical Parameters

Diameter (d-D)	M3
Length (L) (mm)	35
Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

DIN	931
ISO	4014
ISO	4014

Technical Specification

b (min.): L≤125mm	12
k	2
P	0.50
s	5,5

Technical Drawing

