


Structural assembly set EN 15048 Steel Hot dip galvanized 8.8/8 ISO metric M10X50

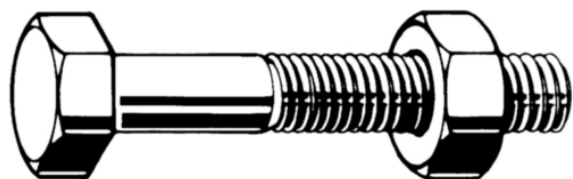

Article No.	01405.100.050
Brand	-
UBB	500574457239
UNSPSC	31161620
EAN	8715494311335
PKG. of 100	Full Box Only

Technical Parameters

Diameter (d-D)	M10
Length (L) (mm)	50
Info	Full boxes only.
Class	8.8
Driving features	Hexagon
Extra info	ISO metric
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Hot dip galvanized
Thread	Metric thread
Wrench width	16

Standards

EN	15048
ISO	4014/4032

Technical Specification

b (min.): L≤125mm	26
P	1.50
k	6.4
s	16
b (min.): L>200mm	45
m (max.)	8.4
b (min.): 125mm<L≤200mm	32

Technical Drawing

