


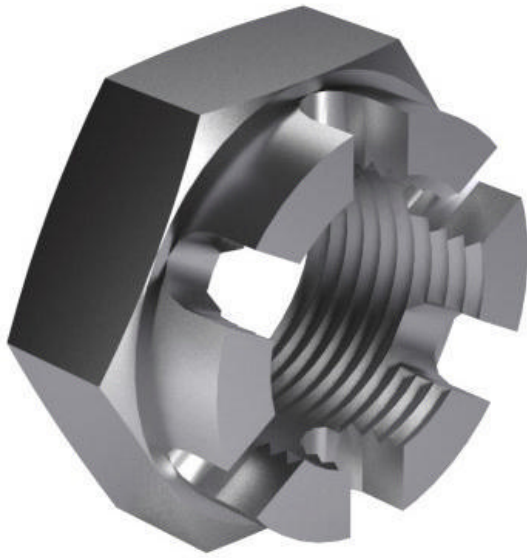

Hexagon thin slotted and castle nut (old type) DIN 937 Steel Plain 17H M8

Article number	01605.080.001
Brand	-
UBB	500648123379
UNSPSC	31161707
EAN	8717077206250
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Class	17H
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	937
-----	-----

Technical Specification

d-D	M8
m	8
n	2.5
P	1.25
s	13
Split pin DIN 94	2

Technical Drawing

