

## Hexagon head bolt DIN 931 Steel Zinc plated yellow passivated 10.9 M12X80/ S=19



Article number	04104.120.080
Brand	-
UBB	500614322120
UNSPSC	31161620
EAN	8715494454933
PKG. of 1	Full Box Only

### Technical Parameters

Diameter (d-D)	M12
Length (L) (mm)	80
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated yellow passivated
Thread	Metric thread
Wrench width (s) (mm)	19
Info	Warning: electroplating of these products may cause hydrogen embrittlement.


### Standards

ASME	B18.2.3.1M
ISO	4014
NF	E25-112
DIN	931

### Technical Specification

b (min.): 125mm<L≤200mm	36
b (min.): L>200mm	49
b (min.): L≤125mm	30
k	7.5

### Technical Drawing

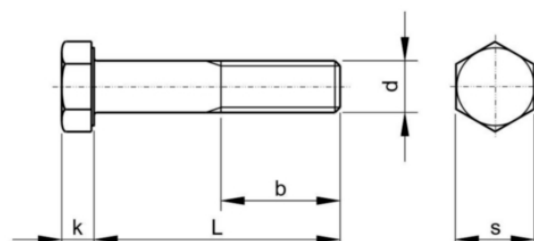

P

1.75

**FABORY**

19