

## Hexagon head bolt DIN 931 Steel Zinc plated yellow passivated 10.9 M14X70/ S=22



Article No.	04104.140.070
Brand	-
UBB	952351489473
UNSPSC	31161620
EAN	8715493175631
PKG. of 1	Full Box Only

### Technical Parameters

Diameter (d-D)	M14
Length (L) (mm)	70
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated yellow passivated
Thread	Metric thread
Wrench width	22
Info	Warning: electroplating of these products may cause hydrogen embrittlement.


### Standards

DIN	931
ISO	4014
NEN	1555
ASME	B18.2.3.1M
NF	E25-112

### Technical Specification

s	22
k	8.8
b (min.): L>200mm	53
P	2
b (min.): 125mm<L≤200mm	40

### Technical Drawing

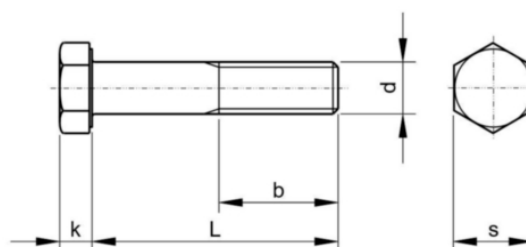

b (min.):  $L \leq 125\text{mm}$  34

