

Hexagon head bolt DIN 931 Steel Zinc plated yellow passivated 10.9 M14X80/ S=22

Article number	04104.140.080
Brand	-
UBB	953351909890
UNSPSC	31161620
EAN	8715493175655
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M14
Length	80 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated yellow passivated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.


Standards

ISO	4014
NF	E25-112
ASME	B18.2.3.1M
NEN	1555
DIN	931

Technical Specification

b (min.): 125mmL≤200mm	40
b (min.): L200mm	53
b (min.): L≤125mm	34
d-D	M14
k	8.8
L (mm)	80

Technical Drawing

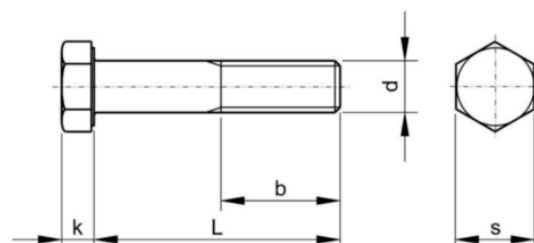

FABORY