

Hexagon head bolt DIN 931 Steel Zinc plated yellow passivated 10.9 M14X90/ S=22

Article number	04104.140.090
Brand	-
UBB	953351910112
UNSPSC	31161620
EAN	8715493175679
PKG. of 1	Full Box Only

Technical Parameters

Diameter	M14
Length	90 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated yellow passivated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.


Standards

ASME	B18.2.3.1M
DIN	931
NEN	1555
ISO	4014
NF	E25-112

Technical Specification

b (min.): 125mmL≤200mm	40
b (min.): L200mm	53
b (min.): L≤125mm	34
d-D	M14
k	8.8
L (mm)	90

Technical Drawing

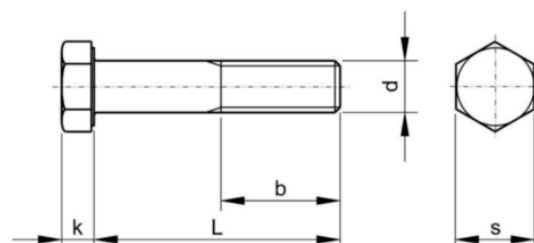

FABORY