


Hexagon head bolt DIN 931 Steel Zinc flake Cr6+free - ISO 10683 flZnnc 10.9 M24X100

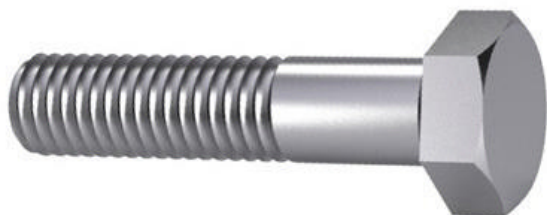

Article No.	04105.240.100
Brand	-
UBB	500505565597
UNSPSC	31161620
EAN	8715494440523
PKG. of 10	Full Box Only

Technical Parameters

Diameter (d-D)	M24
Length (L) (mm)	100
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc flake Cr(VI) free - flZn/nc
Thread	Metric thread
Info	A zinc flake coating eliminates the risk of hydrogen embrittlement.

Standards

DIN	931
ISO	4014
NF	E25-112
ASME	B18.2.3.1M

Technical Specification

b (min.): 125mm<L≤200mm	60
b (min.): L>200mm	73
b (min.): L≤125mm	54
k	15
P	3
s	36

Technical Drawing

