


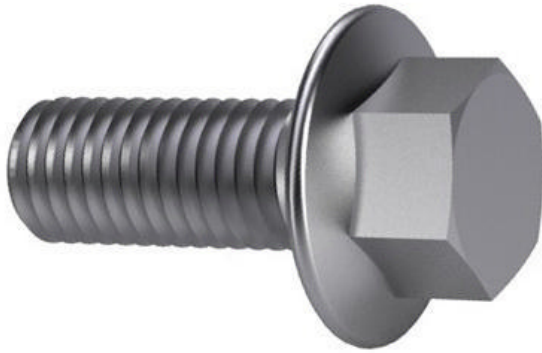

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M6X20

Article number	04140.060.020
Brand	-
UBB	500650799934
UNSPSC	31162400
EAN	8717077294448
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M6
Length	20 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	Warning: electroplating of these products may cause hydrogen embrittlement.

Standards

DIN	≈6921
EN	1665
ISO	≈4162
ASME	≈B18.2.3.4M

Technical Specification

b (min.)	18
d-D	M6
dc (max.)	14.2
k (max.)	6.6
L (mm)	20
P	1
s	10

Technical Drawing

