


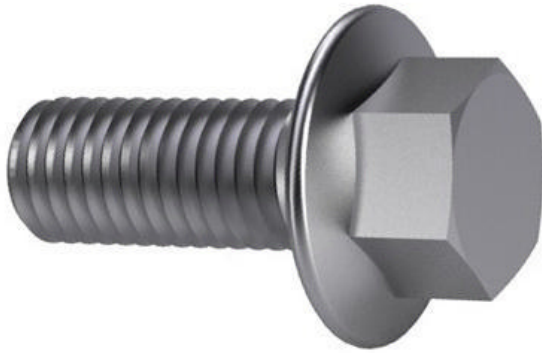

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M6X30

Article number	04140.060.030
Brand	-
UBB	500650800179
UNSPSC	31162400
EAN	8717077294462
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M6
Length	30 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	Warning: electroplating of these products may cause hydrogen embrittlement.

Standards

ISO	≈4162
EN	1665
ASME	≈B18.2.3.4M
DIN	≈6921

Technical Specification

b (min.)	18
d-D	M6
dc (max.)	14.2
k (max.)	6.6
L (mm)	30
P	1
s	10

Technical Drawing

