


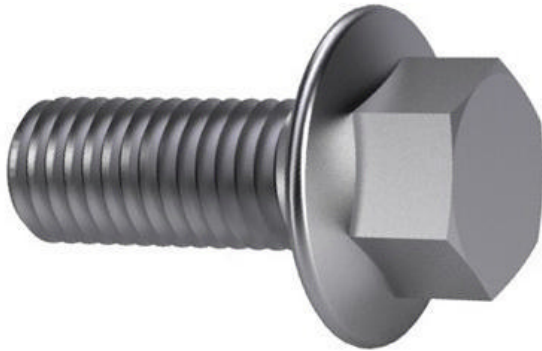

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M12X35

Article number	04140.120.035
Brand	-
UBB	500650801730
UNSPSC	31162400
EAN	8717077294622
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M12
Length	35 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

ASME	≈B18.2.3.4M
EN	1665
DIN	≈6921
ISO	≈4162

Technical Specification

b (min.)	30
d-D	M12
dc (max.)	26.6
k (max.)	11.8
L (mm)	35
P	1.75
s	18

Technical Drawing

