


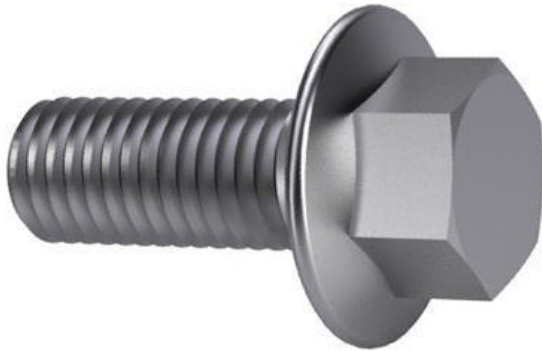

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M16X50

Article number	04140.160.050
Brand	-
UBB	500650802647
UNSPSC	31162400
EAN	8717077294714
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M16
Length	50 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

EN	1665
DIN	≈6921
ISO	≈4162
ASME	≈B18.2.3.4M

Technical Specification

b (min.)	38
d-D	M16
dc (max.)	35
k (max.)	15.4
L (mm)	50
P	2
s	24

Technical Drawing

